


KN-DG12 Cut Sheet

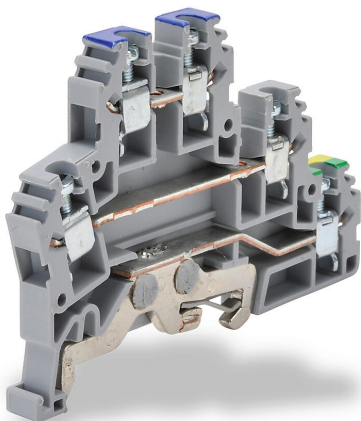

Konnect-It screw double-level feedthrough terminal block, with ground, accepts wire size 26-12 AWG, gray, 20A, 35mm DIN rail mount, 100kA SCCR. Package of 20. For use with jumpers KN-2JTL12, KN-3JTL12, KN-4JTL12 and KN-10JTL12.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-DG12>

Technical Specifications

Brand	Konnect-It
Item	Terminal block
Connector Type	Screw
Terminal Block Type	Double-level feedthrough
Terminal Block Special Feature(s)	With ground
Wire Size	26-12 AWG
Color	Gray

Amperage Rating	20A
Voltage Rating	300V rated (UL)
Mounting	35mm DIN rail
SCCR Rating	100kA SCCR
Quantity per Pack	20
For Use With	Jumpers KN-2JTL12, KN-3JTL12, KN-4JTL12 and KN-10JTL12

Agency Approvals

UL Listed File #	None
UL Recognized File #	E179129
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/KN-DG12.pdf>
See store item page for other formats.