


KN-F10-DCH-10 Cut Sheet

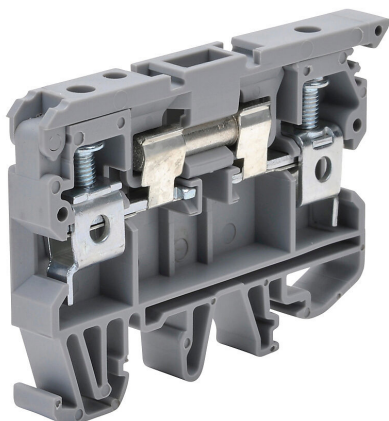

Konnect-It screw disconnect terminal block, accepts wire size 26-8 AWG, gray, 6.3A, 35mm DIN rail mount, 10kA SCCR. Package of 10.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-F10-DCH-10>

Technical Specifications

Brand	Konnect-It
Item	Terminal block
Connector Type	Screw
Terminal Block Type	Disconnect
Wire Size	26-8 AWG
Color	Gray
Amperage Rating	6.3A
Voltage Rating	300V rated (UL)
Mounting	35mm DIN rail
SCCR Rating	10kA SCCR
Quantity per Pack	10
Includes	Copper bar

Agency Approvals

UL Listed File #	None
UL Recognized File #	E179129
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document