


# KN-F10L110DC Cut Sheet

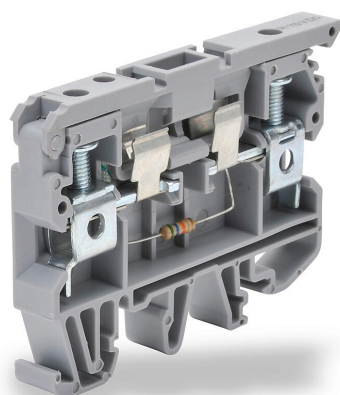

Konnect-It screw circuit protection terminal block, blown fuse indicator, accepts wire size 26-8 AWG, gray, 6.3A, 110 VDC LED indicator(s), 35mm DIN rail mount, 10kA SCCR. Package of 25. For use with GMA, GMC, S500 and S506 series fuses.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-F10L110DC>

## Technical Specifications

Brand	Konnect-It
Item	Terminal block
Connector Type	Screw
Terminal Block Type	Circuit protection
Terminal Block Special Feature(s)	Blown fuse indicator
Accepts Fuse Class	Small dimension (5x20mm)
Wire Size	26-8 AWG
Color	Gray

Amperage Rating	6.3A
Voltage Rating	300V rated (UL)
Indicator	110 VDC LED
Mounting	35mm DIN rail
SCCR Rating	10kA SCCR
Quantity per Pack	25
For Use With	GMA, GMC, S500 and S506 series fuses

## Agency Approvals

UL Listed File #	None
UL Recognized File #	E179129
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/KN-F10L110DC.pdf>  
See store item page for other formats.