


KN-F10L220AC-10 Cut Sheet

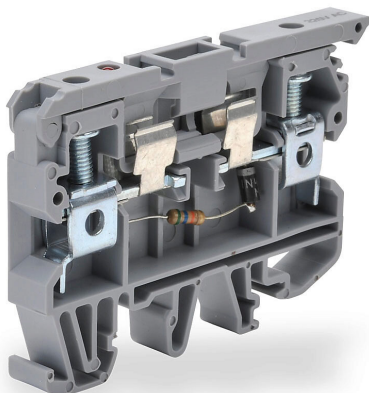

Konnect-It screw circuit protection terminal block, blown fuse indicator, accepts wire size 26–8 AWG, gray, 6.3A, 220 VAC LED indicator(s), 35mm DIN rail mount, 10 kA SCCR. Package of 10. For use with GMA, GMC, S500 and S506 series fuses.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-F10L220AC-10>

Technical Specifications

Brand	Konnect-It
Item	Terminal block
Connector Type	Screw
Terminal Block Type	Circuit protection
Number of Levels	1
Number of Inputs	1
Number of Outputs	1
Interior Connection Type	Fuse holder
Accepts Fuse Class	Small dimension (5x20mm)
Fuse Type	GMA, GMC, S500 and S506 series fuses

Wire Size	26–8 AWG
Color	Gray
Amperage Rating	6.3A
Voltage Rating	300V rated (UL)
Indicator	220 VAC LED
Mounting	35mm DIN rail
SCCR Rating	10 kA SCCR
Quantity per Pack	10
For Use With	GMA, GMC, S500 and S506 series fuses

Agency Approvals

UL Listed File #	None
UL Recognized File #	E179129
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document