


KN-F10L24-NG Cut Sheet

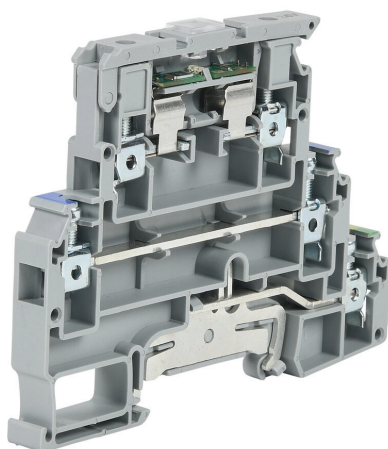

Konnect-It screw multi-function terminal block, triple-level, fuse holder, 1 feedthrough and 1 ground, accepts wire size 24–10 AWG, gray, fused 6.3A, non-fused 30A, fused 24 VAC/VDC, non-fused 300 VAC/VDC, LED indicator(s), 35mm DIN rail mount. Package of 25.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-F10L24-NG>

Technical Specifications

Brand	Konnect-It
Item	Terminal block
Connector Type	Screw
Terminal Block Type	Multi-function
Number of Levels	3
Number of Inputs	3
Number of Outputs	2
Interior Connection Type	Fuse holder, 1 feedthrough and 1 ground
Accepts Fuse Class	Small dimension (5x20mm and 5x25mm)

Fuse Type	GMA, GMC, S500 and S506 series fuses
Wire Size	24–10 AWG
Color	Gray
Amperage Rating	Fused 6.3A, non-fused 30A
Voltage Rating	Fused 24 VAC/VDC, non-fused 300 VAC/VDC
Indicator	LED
Mounting	35mm DIN rail
SCCR Rating	10 kA SCCR
Quantity per Pack	25

Agency Approvals

UL Listed File #	None
UL Recognized File #	E179129
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document
Other	None

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/KN-F10L24-NG.pdf>
See store item page for other formats.