


# KN-F10L24AC-10 Cut Sheet

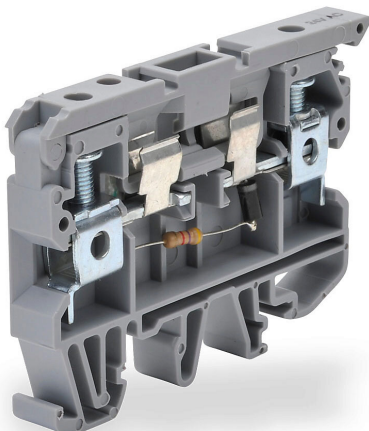

Konnect-It screw circuit protection terminal block, blown fuse indicator, accepts wire size 26-8 AWG, gray, 6.3A, 24 VAC LED indicator(s), 35mm DIN rail mount, 10kA SCCR. Package of 10. For use with GMA, GMC, S500 and S506 series fuses.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-F10L24AC-10>

## Technical Specifications

Brand	Konnect-It	Amperage Rating	6.3A
Item	Terminal block	Voltage Rating	300V rated (UL)
Connector Type	Screw	Indicator	24 VAC LED
Terminal Block Type	Circuit protection	Mounting	35mm DIN rail
Terminal Block Special Feature(s)	Blown fuse indicator	SCCR Rating	10kA SCCR
Accepts Fuse Class	Small dimension (5x20mm)	Quantity per Pack	10
Wire Size	26-8 AWG	For Use With	GMA, GMC, S500 and S506 series fuses
Color	Gray		

## Agency Approvals

UL Listed File #	None
UL Recognized File #	E179129
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>