


# KN-F10L24AC Cut Sheet

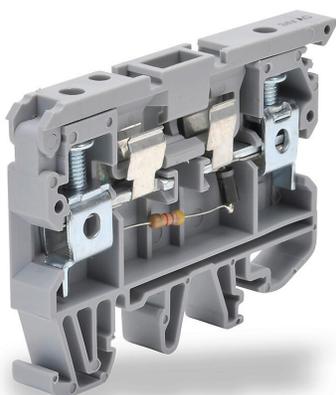

Konnect-It screw circuit protection terminal block, blown fuse indicator, accepts wire size 26-8 AWG, gray, 6.3A, 24 VAC LED indicator(s), 35mm DIN rail mount, 10kA SCCR. Package of 25. For use with GMA, GMC, S500 and S506 series fuses.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-F10L24AC>

## Technical Specifications

<b>Brand</b>	Konnect-It
<b>Item</b>	Terminal block
<b>Connector Type</b>	Screw
<b>Terminal Block Type</b>	Circuit protection
<b>Terminal Block Special Feature(s)</b>	Blown fuse indicator
<b>Accepts Fuse Class</b>	Small dimension (5x20mm)
<b>Wire Size</b>	26-8 AWG
<b>Color</b>	Gray

<b>Amperage Rating</b>	6.3A
<b>Voltage Rating</b>	300V rated (UL)
<b>Indicator</b>	24 VAC LED
<b>Mounting</b>	35mm DIN rail
<b>SCCR Rating</b>	10kA SCCR
<b>Quantity per Pack</b>	25
<b>For Use With</b>	GMA, GMC, S500 and S506 series fuses

## Agency Approvals

<b>UL Listed File #</b>	None
<b>UL Recognized File #</b>	E179129
<b>UL Hazardous File #</b>	None
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	None
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/KN-F10L24AC.pdf>  
See store item page for other formats.