


# KN-G12SP4 Cut Sheet

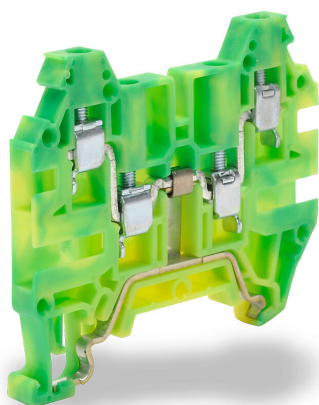

Konnect-It screw grounding terminal block, accepts wire size 26-12 AWG, green and yellow, 35mm DIN rail mount, 100kA SCCR. Package of 25. Use to mechanically and electrically connect wires to 35mm DIN rail through the snap-on clamping foot.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-G12SP4>

## Technical Specifications

Brand	Konnect-It
Item	Terminal block
Connector Type	Screw
Terminal Block Type	Grounding
Wire Size	26-12 AWG
Color	Green and yellow
Mounting	35mm DIN rail
SCCR Rating	100kA SCCR
Quantity per Pack	25
Application	Use to mechanically and electrically connect wires to 35mm DIN rail through the snap-on clamping foot

## Agency Approvals

UL Listed File #	None
UL Recognized File #	E179129
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/KN-G12SP4.pdf>  
See store item page for other formats.