


KN-KBD10 Cut Sheet

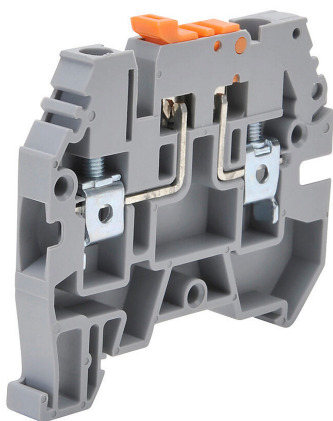

Konnect-It screw disconnect terminal block, accepts wire size 26-10 AWG, gray, 16A, 35mm DIN rail mount, 10kA SCCR. Package of 50.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-KBD10>

Technical Specifications

Brand	Konnect-It
Item	Terminal block
Connector Type	Screw
Terminal Block Type	Disconnect
Wire Size	26-10 AWG
Color	Gray
Amperage Rating	16A
Voltage Rating	600V rated (UL)
Mounting	35mm DIN rail
SCCR Rating	10kA SCCR
Quantity per Pack	50

Agency Approvals

UL Listed File #	None
UL Recognized File #	E179129
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/KN-KBD10.pdf>
See store item page for other formats.