


KN-P1-1-2 Cut Sheet

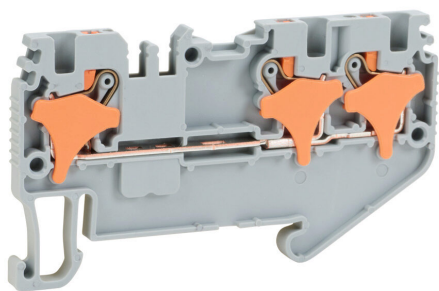

Konnect-It screwless feedthrough terminal block, single-level, 2 inputs to 1 output, accepts wire size 28–14 AWG, gray, 13A, 600 VAC/VDC, 35mm DIN rail mount. Package of 50.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-P1-1-2>

Technical Specifications

Brand	Konnect-It
Item	Terminal block
Connector Type	Screwless
Terminal Block Type	Feedthrough
Number of Levels	1
Number of Inputs	2
Number of Outputs	1
Interior Connection Type	2 inputs to 1 output
Wire Size	28–14 AWG

Color	Gray
Amperage Rating	13A
Voltage Rating	600 VAC/VDC
Mounting	35mm DIN rail
SCCR Rating	10 kA SCCR
Quantity per Pack	50
For Use With	Jumpers KN-P2J1, KN-P3J1, KN-P4J1, KN-P5J1, KN-P10J1

Agency Approvals

UL Listed File #	None
UL Recognized File #	E179129
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/KN-P1-1-2.pdf>
See store item page for other formats.