


# KN-P25-1-PN-25 Cut Sheet

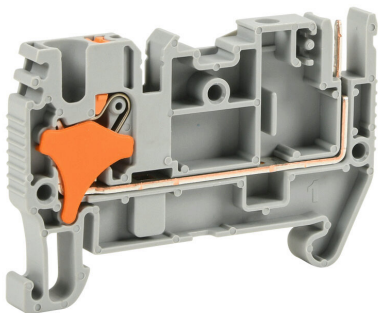

Konnect-It screwless feedthrough terminal block, single-level, pin connection input, accepts wire size 28-12 AWG, gray, 10A, 150 VAC/VDC, 35mm DIN rail mount. Package of 25.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-P25-1-PN-25>

## Technical Specifications

Brand	Konnect-It
Item	Terminal block
Connector Type	Screwless
Terminal Block Type	Feedthrough
Number of Levels	1
Number of Inputs	1
Number of Outputs	1
Interior Connection Type	Pin connection input
Wire Size	28-12 AWG

Color	Gray
Amperage Rating	10A
Voltage Rating	150 VAC/VDC
Mounting	35mm DIN rail
SCCR Rating	10kA SCCR
Quantity per Pack	25
For Use With	Jumpers KN-P2J25, KN-P3J25, KN-P4J25, KN-P5J25, KN-P10J25 and KN-P20J25

## Agency Approvals

UL Listed File #	N/A
UL Recognized File #	E179129
UL Hazardous File #	N/A
CE	<a href="#">View CE declarations</a>
CSA File #	N/A
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/KN-P25-1-PN-25.pdf>  
See store item page for other formats.