


# KN-P25CLD24-25 Cut Sheet

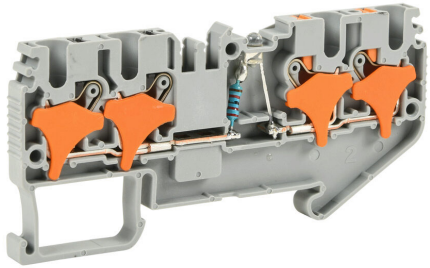

Konnect-It screwless common point feedthrough terminal block, single-level, 2 inputs to 2 outputs bridged with power indicator, accepts wire size 28-12 AWG, gray, 20A, 24 VAC/VDC, LED indicator(s), 35mm DIN rail mount. Package of 25.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-P25CLD24-25>

## Technical Specifications

<b>Brand</b>	Konnect-It	<b>Color</b>	Gray
<b>Item</b>	Terminal block	<b>Amperage Rating</b>	20A
<b>Connector Type</b>	Screwless	<b>Voltage Rating</b>	24 VAC/VDC
<b>Terminal Block Type</b>	Common point feedthrough	<b>Indicator</b>	LED
<b>Number of Levels</b>	1	<b>Mounting</b>	35mm DIN rail
<b>Number of Inputs</b>	2	<b>SCCR Rating</b>	10kA SCCR
<b>Number of Outputs</b>	2	<b>Quantity per Pack</b>	25
<b>Interior Connection Type</b>	2 inputs to 2 outputs bridged with power indicator	<b>For Use With</b>	Jumpers KN-P2J25, KN-P3J25, KN-P4J25, KN-P5J25, KN-P10J25 and KN-P20J25
<b>Wire Size</b>	28-12 AWG		

## Agency Approvals

<b>UL Listed File #</b>	N/A
<b>UL Recognized File #</b>	E179129
<b>UL Hazardous File #</b>	N/A
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	N/A
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/KN-P25CLD24-25.pdf>  
See store item page for other formats.