


# KN-P25DA-1-2 Cut Sheet

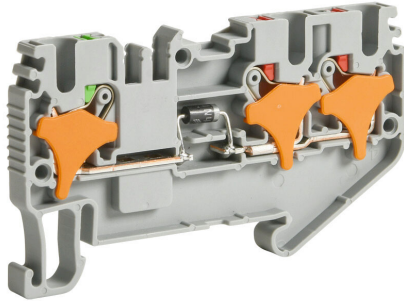

Konnect-It screwless common point feedthrough terminal block, single-level, 2 inputs to 1 output with diode, cathode on input, accepts wire size 28-12 AWG, gray, 1A, 600 VAC/VDC, 35mm DIN rail mount. Package of 50.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-P25DA-1-2>

## Technical Specifications

Brand	Konnect-It
Item	Terminal block
Connector Type	Screwless
Terminal Block Type	Common point feedthrough
Number of Levels	1
Number of Inputs	2
Number of Outputs	1
Interior Connection Type	2 inputs to 1 output with diode, cathode on input
Wire Size	28-12 AWG

Color	Gray
Amperage Rating	1A
Voltage Rating	600 VAC/VDC
Mounting	35mm DIN rail
SCCR Rating	10kA SCCR
Quantity per Pack	50
For Use With	Jumpers KN-P2J25, KN-P3J25, KN-P4J25, KN-P5J25, KN-P10J25 and KN-P20J25

## Agency Approvals

UL Listed File #	N/A
UL Recognized File #	E179129
UL Hazardous File #	N/A
CE	<a href="#">View CE declarations</a>
CSA File #	N/A
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/KN-P25DA-1-2.pdf>  
See store item page for other formats.