


# KN-P25EDB-2-2 Cut Sheet

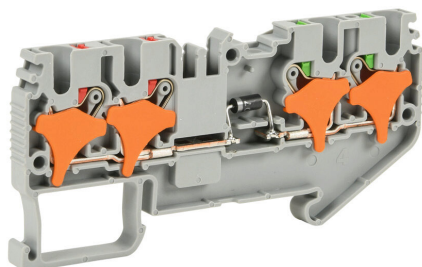

Konnect-It screwless common point feedthrough terminal block, single-level, 2 inputs to 2 outputs bridged with diode, cathode on output, accepts wire size 28-12 AWG, gray, 1A, 600 VAC/VDC, 35mm DIN rail mount. Package of 50.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-P25EDB-2-2>

## Technical Specifications

|                          |                                                             |
|--------------------------|-------------------------------------------------------------|
| Brand                    | Konnect-It                                                  |
| Item                     | Terminal block                                              |
| Connector Type           | Screwless                                                   |
| Terminal Block Type      | Common point feedthrough                                    |
| Number of Levels         | 1                                                           |
| Number of Inputs         | 2                                                           |
| Number of Outputs        | 2                                                           |
| Interior Connection Type | 2 inputs to 2 outputs bridged with diode, cathode on output |

|                   |                                                                         |
|-------------------|-------------------------------------------------------------------------|
| Wire Size         | 28-12 AWG                                                               |
| Color             | Gray                                                                    |
| Amperage Rating   | 1A                                                                      |
| Voltage Rating    | 600 VAC/VDC                                                             |
| Mounting          | 35mm DIN rail                                                           |
| SCCR Rating       | 10kA SCCR                                                               |
| Quantity per Pack | 50                                                                      |
| For Use With      | Jumpers KN-P2J25, KN-P3J25, KN-P4J25, KN-P5J25, KN-P10J25 and KN-P20J25 |

## Agency Approvals

|                      |                                        |
|----------------------|----------------------------------------|
| UL Listed File #     | N/A                                    |
| UL Recognized File # | E179129                                |
| UL Hazardous File #  | N/A                                    |
| CE                   | <a href="#">View CE declarations</a>   |
| CSA File #           | N/A                                    |
| RoHS Status          | Yes (See CE Doc)                       |
| EU REACH             | <a href="#">View EU REACH document</a> |

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/KN-P25EDB-2-2.pdf>  
See store item page for other formats.