


KN-P25LD24-1-PN-25 Cut Sheet

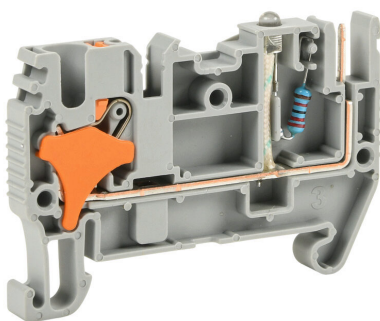

Konnect-It screwless feedthrough terminal block, single-level, pin connection input power indicator, accepts wire size 28-12 AWG, gray, 10A, 24 VAC/VDC, LED indicator(s), 35mm DIN rail mount. Package of 25.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-P25LD24-1-PN-25>

Technical Specifications

Brand	Konnect-It
Item	Terminal block
Connector Type	Screwless
Terminal Block Type	Feedthrough
Number of Levels	1
Number of Inputs	1
Number of Outputs	1
Interior Connection Type	Pin connection input power indicator
Wire Size	28-12 AWG

Color	Gray
Amperage Rating	10A
Voltage Rating	24 VAC/VDC
Indicator	LED
Mounting	35mm DIN rail
SCCR Rating	10kA SCCR
Quantity per Pack	25
For Use With	Jumpers KN-P2J25, KN-P3J25, KN-P4J25, KN-P5J25, KN-P10J25 and KN-P20J25

Agency Approvals

UL Listed File #	N/A
UL Recognized File #	E179129
UL Hazardous File #	N/A
CE	View CE declarations
CSA File #	N/A
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/KN-P25LD24-1-PN-25.pdf>
See store item page for other formats.