


KN-P6-30 Cut Sheet

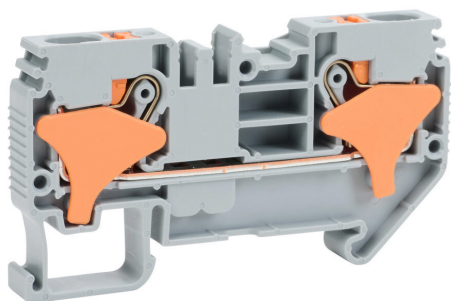

Konnect-It screwless feedthrough terminal block, single-level, accepts wire size 24–8 AWG, gray, 40A, 600 VAC/VDC, 35mm DIN rail mount. Package of 30.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-P6-30>

Technical Specifications

Brand	Konnect-It
Item	Terminal block
Connector Type	Screwless
Terminal Block Type	Feedthrough
Number of Levels	1
Number of Inputs	1
Number of Outputs	1
Wire Size	24–8 AWG

Color	Gray
Amperage Rating	40A
Voltage Rating	600 VAC/VDC
Mounting	35mm DIN rail
SCCR Rating	10 kA SCCR
Quantity per Pack	30
For Use With	Jumpers KN-P2J6, KN-P3J6, KN-P4J6, KN-P5J6, KN-P10J6

Agency Approvals

UL Listed File #	None
UL Recognized File #	E179129
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/KN-P6-30.pdf>
See store item page for other formats.