


KN-PD1C-15 Cut Sheet

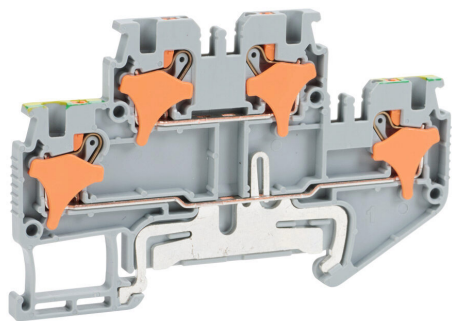

Konnect-It screwless feedthrough terminal block, double-level, with ground and marked for phase and ground, accepts wire size 28–14 AWG, gray, 13A, 300 VAC/VDC, 35mm DIN rail mount. Package of 15.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-PD1C-15>

Technical Specifications

Brand	Konnect-It
Item	Terminal block
Connector Type	Screwless
Terminal Block Type	Feedthrough
Number of Levels	2
Number of Inputs	2
Number of Outputs	2
Interior Connection Type	With ground and marked for phase and ground
Wire Size	28–14 AWG

Color	Gray
Amperage Rating	13A
Voltage Rating	300 VAC/VDC
Mounting	35mm DIN rail
SCCR Rating	10 kA SCCR
Quantity per Pack	15
For Use With	Jumpers KN-P2J1, KN-P3J1, KN-P4J1, KN-P5J1, KN-P10J1

Agency Approvals

UL Listed File #	None
UL Recognized File #	E179129
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/KN-PD1C-15.pdf>
See store item page for other formats.