


# KN-PD25DB Cut Sheet

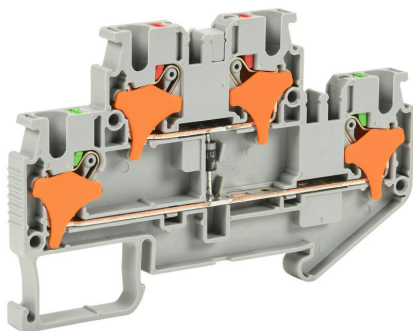

Konnect-It screwless feedthrough terminal block, double-level, 1 diode connected between levels, cathode on top level, accepts wire size 28-12 AWG, gray, 1A, 300 VAC/VDC, 35mm DIN rail mount. Package of 25.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-PD25DB>

## Technical Specifications

Brand	Konnect-It	Wire Size	28-12 AWG
Item	Terminal block	Color	Gray
Connector Type	Screwless	Amperage Rating	1A
Terminal Block Type	Feedthrough	Voltage Rating	300 VAC/VDC
Number of Levels	2	Mounting	35mm DIN rail
Number of Inputs	2	SCCR Rating	10kA SCCR
Number of Outputs	2	Quantity per Pack	25
Interior Connection Type	1 diode connected between levels, cathode on top level	For Use With	Jumpers KN-P2J25, KN-P3J25, KN-P4J25, KN-P5J25, KN-P10J25 and KN-P20J25

## Agency Approvals

UL Listed File #	N/A
UL Recognized File #	E179129
UL Hazardous File #	N/A
CE	<a href="#">View CE declarations</a>
CSA File #	N/A
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/KN-PD25DB.pdf>  
See store item page for other formats.