


KN-PG1E-1-2-25 Cut Sheet

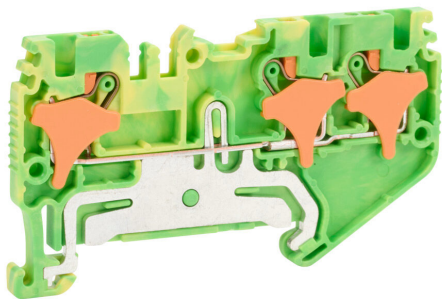

Konnect-It screwless grounding terminal block, single-level, 2 inputs to 1 output, accepts wire size 28–14 AWG, yellow/green, 600 VAC/VDC, 35mm DIN rail mount. Package of 25.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-PG1E-1-2-25>

Technical Specifications

Brand	Konnect-It	Wire Size	28–14 AWG
Item	Terminal block	Color	Yellow/green
Connector Type	Screwless	Voltage Rating	600 VAC/VDC
Terminal Block Type	Grounding	Mounting	35mm DIN rail
Number of Levels	1	SCCR Rating	10 kA SCCR
Number of Inputs	2	Quantity per Pack	25
Number of Outputs	1	Application	Use to mechanically and electrically connect wires to 35mm DIN rail through the clamping foot
Interior Connection Type	2 inputs to 1 output		

Agency Approvals

UL Listed File #	None
UL Recognized File #	E179129
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/KN-PG1E-1-2-25.pdf>
See store item page for other formats.