


# KN-PG25-2-2 Cut Sheet

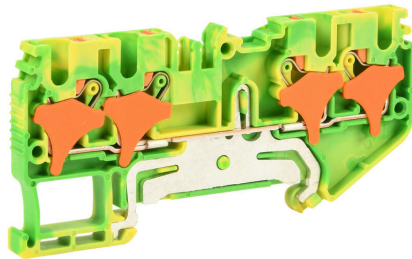

Konnect-It screwless grounding terminal block, single-level, 2 inputs to 2 outputs, accepts wire size 28-12 AWG, yellow/green, 600 VAC/VDC, 35mm DIN rail mount. Package of 50.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-PG25-2-2>

## Technical Specifications

<b>Brand</b>	Konnect-It
<b>Item</b>	Terminal block
<b>Connector Type</b>	Screwless
<b>Terminal Block Type</b>	Grounding
<b>Number of Levels</b>	1
<b>Number of Inputs</b>	2
<b>Number of Outputs</b>	2
<b>Interior Connection Type</b>	2 inputs to 2 outputs

<b>Wire Size</b>	28-12 AWG
<b>Color</b>	Yellow/green
<b>Voltage Rating</b>	600 VAC/VDC
<b>Mounting</b>	35mm DIN rail
<b>SCCR Rating</b>	10kA SCCR
<b>Quantity per Pack</b>	50
<b>Application</b>	Use to mechanically and electrically connect wires to 35mm DIN rail through the clamping foot

## Agency Approvals

<b>UL Listed File #</b>	N/A
<b>UL Recognized File #</b>	E179129
<b>UL Hazardous File #</b>	N/A
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	N/A
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/KN-PG25-2-2.pdf>  
See store item page for other formats.