


# KN-PG4-2-2-25 Cut Sheet

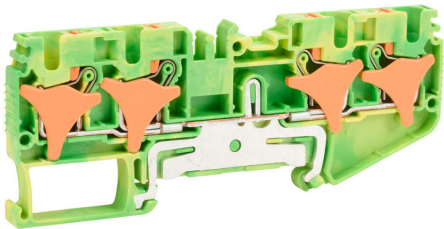

Konnect-It screwless grounding terminal block, single-level, 2 inputs to 2 outputs, accepts wire size 28–10 AWG, yellow/green, 600 VAC/VDC, 35mm DIN rail mount. Package of 25.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-PG4-2-2-25>

## Technical Specifications

|                          |                       |
|--------------------------|-----------------------|
| Brand                    | Konnect-It            |
| Item                     | Terminal block        |
| Connector Type           | Screwless             |
| Terminal Block Type      | Grounding             |
| Number of Levels         | 1                     |
| Number of Inputs         | 2                     |
| Number of Outputs        | 2                     |
| Interior Connection Type | 2 inputs to 2 outputs |

|                   |                                                                                               |
|-------------------|-----------------------------------------------------------------------------------------------|
| Wire Size         | 28–10 AWG                                                                                     |
| Color             | Yellow/green                                                                                  |
| Voltage Rating    | 600 VAC/VDC                                                                                   |
| Mounting          | 35mm DIN rail                                                                                 |
| SCCR Rating       | 10 kA SCCR                                                                                    |
| Quantity per Pack | 25                                                                                            |
| Application       | Use to mechanically and electrically connect wires to 35mm DIN rail through the clamping foot |

## Agency Approvals

|                      |                                        |
|----------------------|----------------------------------------|
| UL Listed File #     | None                                   |
| UL Recognized File # | E179129                                |
| UL Hazardous File #  | None                                   |
| CE                   | <a href="#">View CE declarations</a>   |
| CSA File #           | None                                   |
| RoHS Status          | Yes (See CE Doc)                       |
| EU REACH             | <a href="#">View EU REACH document</a> |

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/KN-PG4-2-2-25.pdf>  
See store item page for other formats.