


KN-PG4-2-2 Cut Sheet

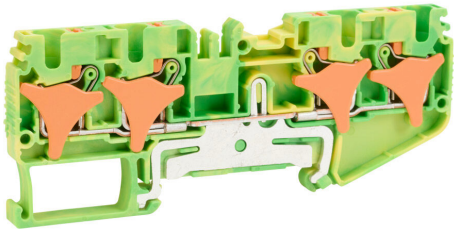

Konnect-It screwless grounding terminal block, single-level, 2 inputs to 2 outputs, accepts wire size 28–10 AWG, yellow/green, 600 VAC/VDC, 35mm DIN rail mount. Package of 50.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-PG4-2-2>

Technical Specifications

Brand	Konnect-It
Item	Terminal block
Connector Type	Screwless
Terminal Block Type	Grounding
Number of Levels	1
Number of Inputs	2
Number of Outputs	2
Interior Connection Type	2 inputs to 2 outputs

Wire Size	28–10 AWG
Color	Yellow/green
Voltage Rating	600 VAC/VDC
Mounting	35mm DIN rail
SCCR Rating	10 kA SCCR
Quantity per Pack	50
Application	Use to mechanically and electrically connect wires to 35mm DIN rail through the clamping foot

Agency Approvals

UL Listed File #	None
UL Recognized File #	E179129
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/KN-PG4-2-2.pdf>
See store item page for other formats.