


KN-PG6 Cut Sheet

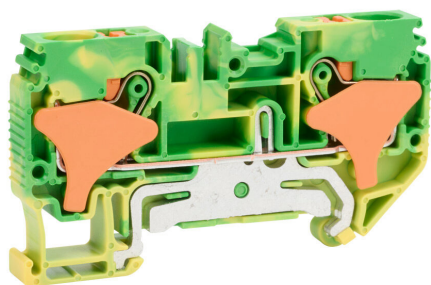

Konnect-It screwless grounding terminal block, single-level, accepts wire size 24–8 AWG, yellow/green, 600 VAC/VDC, 35mm DIN rail mount. Package of 60.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-PG6>

Technical Specifications

Brand	Konnect-It
Item	Terminal block
Connector Type	Screwless
Terminal Block Type	Grounding
Number of Levels	1
Number of Inputs	1
Number of Outputs	1
Wire Size	24–8 AWG

Color	Yellow/green
Voltage Rating	600 VAC/VDC
Mounting	35mm DIN rail
SCCR Rating	10 kA SCCR
Quantity per Pack	60
Application	Use to mechanically and electrically connect wires to 35mm DIN rail through the clamping foot

Agency Approvals

UL Listed File #	None
UL Recognized File #	E179129
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/KN-PG6.pdf>
See store item page for other formats.