


KN-PT25LD220-25 Cut Sheet

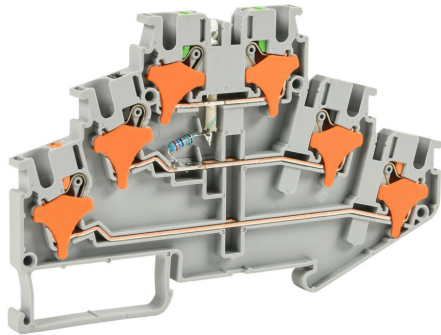

Konnect-It screwless feedthrough terminal block, triple-level, power indicator between levels 2 and 3, accepts wire size 28-12 AWG, gray, 20A, 220 VAC/VDC, LED indicator(s), 35mm DIN rail mount. Package of 25.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-PT25LD220-25>

Technical Specifications

| | |
|---------------------------------|--|
| Brand | Konnect-It |
| Item | Terminal block |
| Connector Type | Screwless |
| Terminal Block Type | Feedthrough |
| Number of Levels | 3 |
| Number of Inputs | 3 |
| Number of Outputs | 3 |
| Interior Connection Type | Power indicator between levels 2 and 3 |
| Wire Size | 28-12 AWG |

| | |
|--------------------------|---|
| Color | Gray |
| Amperage Rating | 20A |
| Voltage Rating | 220 VAC/VDC |
| Indicator | LED |
| Mounting | 35mm DIN rail |
| SCCR Rating | 10kA SCCR |
| Quantity per Pack | 25 |
| For Use With | Jumpers KN-P2J25, KN-P3J25, KN-P4J25, KN-P5J25, KN-P10J25 and KN-P20J25 |

Agency Approvals

| | |
|-----------------------------|--|
| UL Listed File # | N/A |
| UL Recognized File # | E179129 |
| UL Hazardous File # | N/A |
| CE | View CE declarations |
| CSA File # | N/A |
| RoHS Status | Yes (See CE Doc) |
| EU REACH | View EU REACH document |

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/KN-PT25LD220-25.pdf>
See store item page for other formats.