


# KN-PT25LD24 Cut Sheet

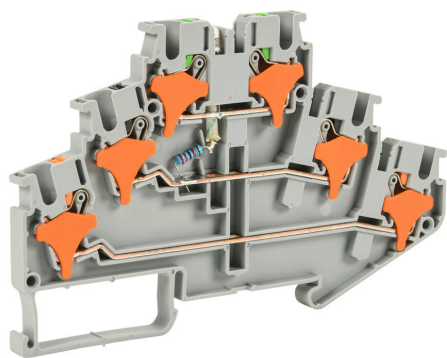

Konnect-It screwless feedthrough terminal block, triple-level, power indicator between levels 2 and 3, accepts wire size 28-12 AWG, gray, 20A, 24 VAC/VDC, LED indicator(s), 35mm DIN rail mount. Package of 50.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-PT25LD24>

## Technical Specifications

|                          |                                        |
|--------------------------|----------------------------------------|
| Brand                    | Konnect-It                             |
| Item                     | Terminal block                         |
| Connector Type           | Screwless                              |
| Terminal Block Type      | Feedthrough                            |
| Number of Levels         | 3                                      |
| Number of Inputs         | 3                                      |
| Number of Outputs        | 3                                      |
| Interior Connection Type | Power indicator between levels 2 and 3 |
| Wire Size                | 28-12 AWG                              |

|                   |                                                                         |
|-------------------|-------------------------------------------------------------------------|
| Color             | Gray                                                                    |
| Amperage Rating   | 20A                                                                     |
| Voltage Rating    | 24 VAC/VDC                                                              |
| Indicator         | LED                                                                     |
| Mounting          | 35mm DIN rail                                                           |
| SCCR Rating       | 10kA SCCR                                                               |
| Quantity per Pack | 50                                                                      |
| For Use With      | Jumpers KN-P2J25, KN-P3J25, KN-P4J25, KN-P5J25, KN-P10J25 and KN-P20J25 |

## Agency Approvals

|                      |                                        |
|----------------------|----------------------------------------|
| UL Listed File #     | N/A                                    |
| UL Recognized File # | E179129                                |
| UL Hazardous File #  | N/A                                    |
| CE                   | <a href="#">View CE declarations</a>   |
| CSA File #           | N/A                                    |
| RoHS Status          | Yes (See CE Doc)                       |
| EU REACH             | <a href="#">View EU REACH document</a> |

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/KN-PT25LD24.pdf>  
See store item page for other formats.