


# KN-T12WHT-100 Cut Sheet

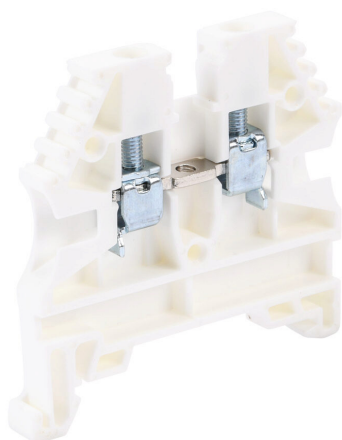

Konnect-It screw single-level feedthrough terminal block, accepts wire size 26-12 AWG, white, 20A, 35mm DIN rail mount, 100kA SCCR. Package of 100. For use with jumpers KN-2J12, KN-3J12, KN-4J12 and KN-10J12.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-T12WHT-100>

## Technical Specifications

|                     |  |
|---------------------|--|
| Brand               | Konnect-It                                     |
| Item                | Terminal block                                 |
| Connector Type      | Screw  |
| Terminal Block Type | Single-level feedthrough                       |
| Wire Size           | 26-12 AWG                                      |
| Color               | White  |
| Amperage Rating     | 20A  |
| Voltage Rating      | 600V rated (UL)                                |
| Mounting            | 35mm DIN rail                                  |
| SCCR Rating         | 100kA SCCR                                     |
| Quantity per Pack   | 100  |
| For Use With        | Jumpers KN-2J12, KN-3J12, KN-4J12 and KN-10J12 |

## Agency Approvals

|                      |  |
|----------------------|--|
| UL Listed File #     | None                                   |
| UL Recognized File # | E179129                                |
| UL Hazardous File #  | None                                   |
| CE                   | <a href="#">View CE declarations</a>   |
| CSA File #           | None                                   |
| RoHS Status          | Yes (See CE Doc)                       |
| EU REACH             | <a href="#">View EU REACH document</a> |