


# KN-T4BLU Cut Sheet

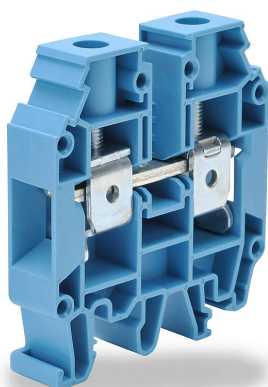

Konnect-It screw single-level feedthrough terminal block, accepts wire size 12-4 AWG, blue, 80A, 35mm DIN rail mount, 100kA SCCR. Package of 50. For use with jumpers KN-2J4, KN-3J4, KN-4J4 and KN-10J4.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-T4BLU>

## Technical Specifications

Brand	Konnect-It
Item	Terminal block
Connector Type	Screw
Terminal Block Type	Single-level feedthrough
Wire Size	12-4 AWG
Color	Blue
Amperage Rating	80A
Voltage Rating	600V rated (UL)
Mounting	35mm DIN rail
SCCR Rating	100kA SCCR
Quantity per Pack	50
For Use With	Jumpers KN-2J4, KN-3J4, KN-4J4 and KN-10J4

## Agency Approvals

UL Listed File #	None
UL Recognized File #	E179129
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/KN-T4BLU.pdf>  
See store item page for other formats.