


# KN-T6YEL-25 Cut Sheet

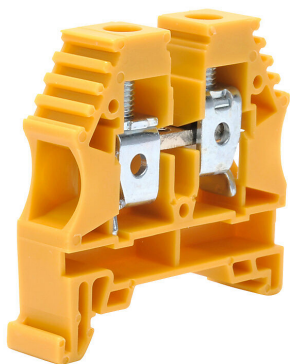

Konnect-It screw single-level feedthrough terminal block, accepts wire size 16-6 AWG, yellow, 65A, 35mm DIN rail mount, 100kA SCCR. Package of 25. For use with jumpers KN-2J6, KN-3J6, KN-4J6 and KN-10J6.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-T6YEL-25>

## Technical Specifications

Brand	Konnect-It
Item	Terminal block
Connector Type	Screw
Terminal Block Type	Single-level feedthrough
Wire Size	16-6 AWG
Color	Yellow
Amperage Rating	65A
Voltage Rating	300 VAC/VDC (UL usage groups B & C), 600 VAC/VDC (UL usage group D)
Mounting	35mm DIN rail
SCCR Rating	100kA SCCR
Quantity per Pack	25
For Use With	Jumpers KN-2J6, KN-3J6, KN-4J6 and KN-10J6

## Agency Approvals

UL Listed File #	None
UL Recognized File #	E179129
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>