


KN-T8ORG-60 Cut Sheet

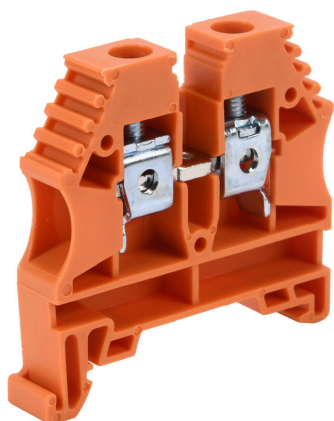

Konnect-It screw single-level feedthrough terminal block, accepts wire size 26-8 AWG, orange, 50A, 35mm DIN rail mount, 100kA SCCR. Package of 60. For use with jumpers KN-2J8, KN-3J8, KN-4J8 and KN-10J8.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-T8ORG-60>

Technical Specifications

| | |
|----------------------------|---|
| Brand | Konnect-It |
| Item | Terminal block |
| Connector Type | Screw |
| Terminal Block Type | Single-level feedthrough |
| Wire Size | 26-8 AWG |
| Color | Orange |
| Amperage Rating | 50A |
| Voltage Rating | 300 VAC/VDC (UL usage groups B & C), 600 VAC/VDC (UL usage group D) |
| Mounting | 35mm DIN rail |
| SCCR Rating | 100kA SCCR |
| Quantity per Pack | 60 |
| For Use With | Jumpers KN-2J8, KN-3J8, KN-4J8 and KN-10J8 |

Agency Approvals

| | |
|-----------------------------|--|
| UL Listed File # | None |
| UL Recognized File # | E179129 |
| UL Hazardous File # | None |
| CE | View CE declarations |
| CSA File # | None |
| RoHS Status | Yes (See CE Doc) |
| EU REACH | View EU REACH document |