


# KN-T8YEL-20 Cut Sheet

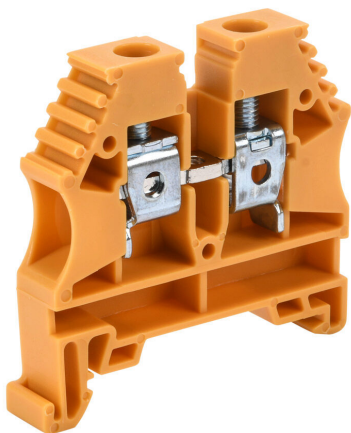

Konnect-It screw single-level feedthrough terminal block, accepts wire size 26-8 AWG, yellow, 50A, 35mm DIN rail mount, 100kA SCCR. Package of 20. For use with jumpers KN-2J8, KN-3J8, KN-4J8 and KN-10J8.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-T8YEL-20>

## Technical Specifications

Brand	Konnect-It
Item	Terminal block
Connector Type	Screw
Terminal Block Type	Single-level feedthrough
Wire Size	26-8 AWG
Color	Yellow
Amperage Rating	50A
Voltage Rating	300 VAC/VDC (UL usage groups B & C), 600 VAC/VDC (UL usage group D)
Mounting	35mm DIN rail
SCCR Rating	100kA SCCR
Quantity per Pack	20
For Use With	Jumpers KN-2J8, KN-3J8, KN-4J8 and KN-10J8

## Agency Approvals

UL Listed File #	None
UL Recognized File #	E179129
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>