


# KN-TL14SLP Cut Sheet

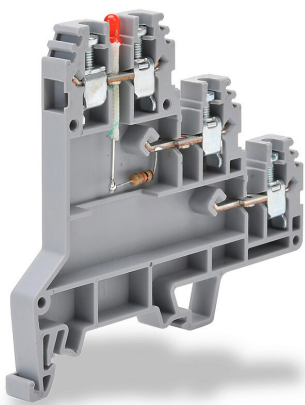

Konnect-It screw triple-level sensor terminal block, connected between levels and power indicator, accepts wire size 24-12 AWG, gray, 24A, PNP LED indicator(s), 35mm DIN rail mount, 100kA SCCR. Package of 20.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/KN-TL14SLP>

## Technical Specifications

Brand	Konnect-It
Item	Terminal block
Connector Type	Screw
Terminal Block Type	Triple-level sensor
Terminal Block Special Feature(s)	Connected between levels and power indicator
Wire Size	24-12 AWG
Color	Gray
Amperage Rating	24A

Voltage Rating	24 VDC
Indicator	PNP LED
Mounting	35mm DIN rail
SCCR Rating	100kA SCCR
Quantity per Pack	20
For Use With	Jumpers KN-2JTL12, KN-3JTL12, KN-4JTL12 and KN-10JTL12
Application	For PNP type sensors

## Agency Approvals

UL Listed File #	None
UL Recognized File #	E179129
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/KN-TL14SLP.pdf>  
See store item page for other formats.