


# L601605-1 Cut Sheet

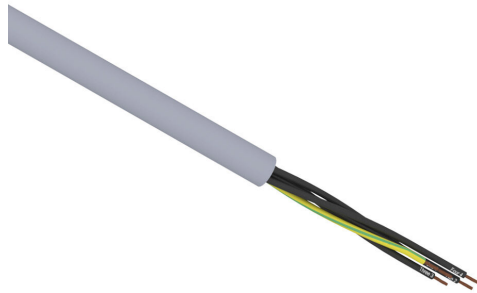

Lapp OLFLEX 190 flexible control cable, unshielded, 5 conductors (includes ground), 16 AWG, bare copper, PVC conductor insulation material, black with white numbers and green/yellow ground, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/L601605-1>

## Technical Specifications

|                             |  |
|-----------------------------|--|
| <b>Brand</b>                | Lapp   |
| <b>Item</b>                 | Cable  |
| <b>Series</b>               | OLFLEX 190                                       |
| <b>Wire/Cable Type</b>      | Control  |
| <b>UL Wire/Cable Type</b>   | TC-ER and WTTC                                   |
| <b>Applicable Standards</b> | UL 1277, UL 2277, ECOLAB and NFPA 79             |
| <b>Application</b>          | General purpose                                  |
| <b>Flexibility</b>          | Flexible   |
| <b>Voltage Rating</b>       | 600V (Type TC-ER), 1000V (Type WTTC, UL/CSA AWM) |
| <b>Conductors</b>           | 5 conductors (includes ground)                   |
| <b>Conductor Size</b>       | 16 AWG   |

|                                       |  |
|---------------------------------------|--|
| <b>Conductor Stranding</b>            | 30-stranded                                      |
| <b>Conductor Material</b>             | Bare copper                                      |
| <b>Conductor Insulation Material</b>  | PVC  |
| <b>Conductor Insulation Color</b>     | Black with white numbers and green/yellow ground |
| <b>Shielding</b>                      | Unshielded                                       |
| <b>Jacket Material</b>                | PVC  |
| <b>Jacket Color</b>                   | Gray   |
| <b>Nominal Overall Cable Diameter</b> | 0.375in  |
| <b>Bulk Length</b>                    | Cut to length                                    |

## Agency Approvals

|                             |  |
|-----------------------------|--|
| <b>UL Listed File #</b>     | E171371                                |
| <b>UL Recognized File #</b> | None                                   |
| <b>UL Hazardous File #</b>  | None                                   |
| <b>CE</b>                   | <a href="#">View CE declarations</a>   |
| <b>CSA File #</b>           | LL94629                                |
| <b>RoHS Status</b>          | Yes (See CE Doc)                       |
| <b>EU REACH</b>             | <a href="#">View EU REACH document</a> |