


L602003-1 Cut Sheet

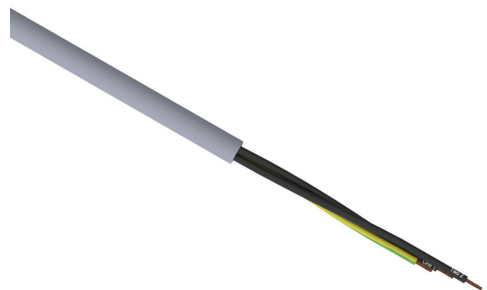

Lapp OLFLEX 190 flexible control cable, unshielded, 3 conductors (includes ground), 20 AWG, bare copper, PVC conductor insulation material, black with white numbers and green/yellow ground, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/L602003-1>

Technical Specifications

| | |
|-----------------------------|---|
| Brand | Lapp |
| Item | Cable |
| Series | OLFLEX 190 |
| Wire/Cable Type | Control |
| UL Wire/Cable Type | PLTC-ER |
| Applicable Standards | UL 13, ECOLAB and NFPA 79 |
| Application | General purpose |
| Flexibility | Flexible |
| Voltage Rating | 300V (Type PLTC-ER), 1000V (UL/CSA AWM) |
| Conductors | 3 conductors (includes ground) |
| Conductor Size | 20 AWG |

| | |
|---------------------------------------|--|
| Conductor Stranding | 16-stranded |
| Conductor Material | Bare copper |
| Conductor Insulation Material | PVC |
| Conductor Insulation Color | Black with white numbers and green/yellow ground |
| Shielding | Unshielded |
| Jacket Material | PVC |
| Jacket Color | Gray |
| Nominal Overall Cable Diameter | 0.265in |
| Bulk Length | Cut to length |

Agency Approvals

| | |
|-----------------------------|--|
| UL Listed File # | E216027 |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | View CE declarations |
| CSA File # | LL94629 |
| RoHS Status | Yes (See CE Doc) |
| EU REACH | View EU REACH document |