


LA-0-5 Cut Sheet

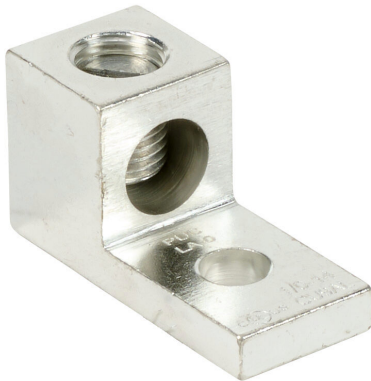

Penn-Union mechanical lug, box type, tin-plated aluminum, 600V, 1 openings, (1) 14-1/0 AWG stranded copper, (2) 14-4 AWG stranded copper, (1) 12-1/0 AWG stranded aluminum or (2) 12-4 AWG stranded aluminum, AL9CU. Package of 5.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/LA-0-5>

Technical Specifications

Brand	Penn-Union
Item	Mechanical lug
Lug Type	Box type
Material	Tin-plated aluminum
Voltage Rating	600V
Number Of Openings	1
Tightening Torque	50 in-lb copper or 35 in-lb aluminum
Conductor Bolt Style	Slotted set screw

Conductor Material	Copper or aluminum
Conductor Size	(1) 14-1/0 AWG stranded copper, (2) 14-4 AWG stranded copper, (1) 12-1/0 AWG stranded aluminum or (2) 12-4 AWG stranded aluminum
Mounting Holes	1-hole
Mounting Bolt Size	1/4in
Dual Rating	AL9CU
Quantity per Pack	5

Agency Approvals

UL Listed File #	E12822
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/LA-0-5.pdf>
See store item page for other formats.