


LR2-10P5-1PH-A Cut Sheet

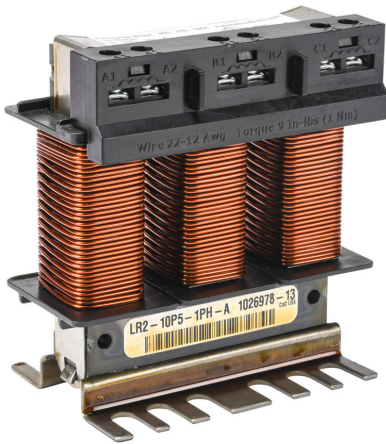

AutomationDirect LR2 series line reactor, 110 VAC, 1/2hp, 1-phase, 12A, 3% impedance, input side only. For use with multiple AC drives.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/LR2-10P5-1PH-A>

Technical Specifications

Brand	AutomationDirect
Item	Line reactor
Series	LR2
Voltage Rating	110 VAC
Horsepower Rating	1/2hp
Number of Phases	1
Amperage Rating	12A
Impedance	3%
Orientation	Input side only
For Use With	Multiple AC drives

Agency Approvals

UL Listed File #	E197592
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/LR2-10P5-1PH-A.pdf>
See store item page for other formats.