


# LR2-21P5-1PH-A Cut Sheet

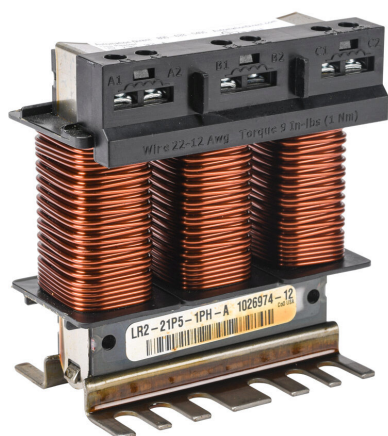

AutomationDirect LR2 series line reactor, 230 VAC, 1-1/2hp, 1-phase, 11.6A, 3% impedance, input side only. For use with multiple AC drives.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/LR2-21P5-1PH-A>

## Technical Specifications

<b>Brand</b>	AutomationDirect
<b>Item</b>	Line reactor
<b>Series</b>	LR2
<b>Voltage Rating</b>	230 VAC
<b>Horsepower Rating</b>	1-1/2hp
<b>Number of Phases</b>	1
<b>Amperage Rating</b>	11.6A
<b>Impedance</b>	3%
<b>Orientation</b>	Input side only
<b>For Use With</b>	Multiple AC drives

## Agency Approvals

<b>UL Listed File #</b>	E197592
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	None
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/LR2-21P5-1PH-A.pdf>  
See store item page for other formats.