


# LR2-40P3 Cut Sheet

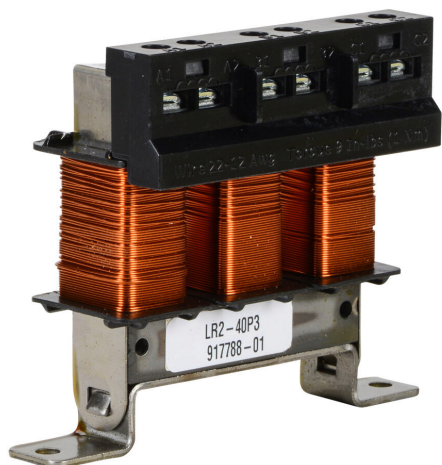

AutomationDirect LR2 series line reactor, 460 VAC, 1/3hp, 3-phase, 0.8A, 3% impedance, input or output side. For use with multiple AC drives.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/LR2-40P3>

## Technical Specifications

Brand	AutomationDirect
Item	Line reactor
Series	LR2
Voltage Rating	460 VAC
Horsepower Rating	1/3hp
Number of Phases	3
Amperage Rating	0.8A
Impedance	3%
Orientation	Input or output side
For Use With	Multiple AC drives

## Agency Approvals

UL Listed File #	E197592
UL Recognized File #	None
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/LR2-40P3.pdf>  
See store item page for other formats.