


LR2-40P5 Cut Sheet

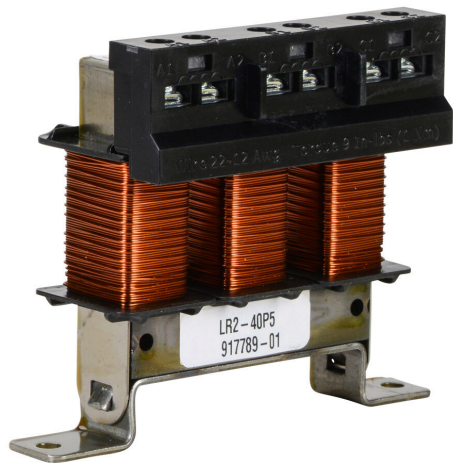

AutomationDirect LR2 series line reactor, 460 VAC, 1/2hp, 3-phase, 1.1A, 3% impedance, input or output side. For use with multiple AC drives.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/LR2-40P5>

Technical Specifications

Brand	AutomationDirect
Item	Line reactor
Series	LR2
Voltage Rating	460 VAC
Horsepower Rating	1/2hp
Number of Phases	3
Amperage Rating	1.1A
Impedance	3%
Orientation	Input or output side
For Use With	Multiple AC drives

Agency Approvals

UL Listed File #	E197592
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/LR2-40P5.pdf>
See store item page for other formats.