


LR2-41P5 Cut Sheet

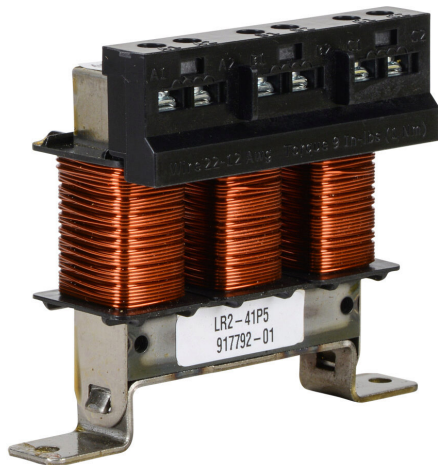

AutomationDirect LR2 series line reactor, 460 VAC, 1-1/2hp, 3-phase, 3A, 3% impedance, input or output side. For use with multiple AC drives.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/LR2-41P5>

Technical Specifications

| | |
|--------------------------|----------------------|
| Brand | AutomationDirect |
| Item | Line reactor |
| Series | LR2 |
| Voltage Rating | 460 VAC |
| Horsepower Rating | 1-1/2hp |
| Number of Phases | 3 |
| Amperage Rating | 3A |
| Impedance | 3% |
| Orientation | Input or output side |
| For Use With | Multiple AC drives |

Agency Approvals

| | |
|-----------------------------|--|
| UL Listed File # | E197592 |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | View CE declarations |
| CSA File # | None |
| RoHS Status | Yes (See CE Doc) |
| EU REACH | View EU REACH document |