


# ME4M-14R-SS Cut Sheet

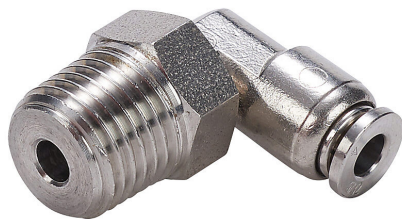

NITRA pneumatic push-to-connect fitting, male, elbow, rotating, 316 stainless steel body, 316 stainless steel threads, 5/32in (4mm) tube to R1/4 BSPT connection(s).

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/ME4M-14R-SS>

## Technical Specifications

<b>Brand</b>	NITRA
<b>Item</b>	Pneumatic Push-to-connect Fitting
<b>Gender</b>	Male
<b>Fitting Type</b>	Elbow
<b>Fitting Function</b>	Rotating
<b>Body Material</b>	316 stainless steel
<b>Thread Material</b>	316 stainless steel
<b>Thread Sealant</b>	No
<b>Connection</b>	5/32in (4mm) push-to-connect and R1/4 BSPT
<b>Operating Pressure</b>	-29.5in Hg to 290 psi
<b>Operating Temperature</b>	32 to 390 deg F
<b>For Use With</b>	Flexible pneumatic tubing

## Agency Approvals

<b>UL Listed File #</b>	None
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	None
<b>CSA File #</b>	None
<b>RoHS Status</b>	No
<b>EU REACH</b>	<a href="#">View EU REACH document</a>