


ME6M-18R-B Cut Sheet

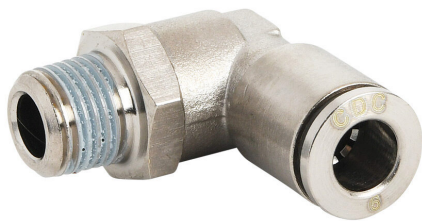

NITRA pneumatic push-to-connect fitting, elbow, rotating, nickel-plated brass body, nickel-plated brass threads, thread sealant, (1) R1/8 male BSPT to (1) 6mm push-to-connect. Package of 5.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/ME6M-18R-B>

Technical Specifications

Brand	NITRA
Item	Fitting
Working Fluid	Air or inert gas
Fitting Connection Type	Push-to-connect
Fitting Type	Elbow
Fitting Function	Rotating
Body Material	Nickel-plated brass
Thread Material	Nickel-plated brass

Thread Sealant	Yes
Fitting Measurement Type	Metric and SAE
Connection	(1) R1/8 male BSPT and (1) 6mm push-to-connect
Operating Pressure	0 to 300 psi
Operating Temperature	0 to 175 deg F
Quantity per Pack	5
For Use With	Flexible pneumatic tubing

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/ME6M-18R-B.pdf>
See store item page for other formats.