


ME6M-18R-SS Cut Sheet

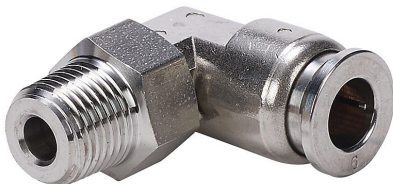

NITRA pneumatic push-to-connect fitting, male, elbow, rotating, 316 stainless steel body, 316 stainless steel threads, 6mm tube to R1/8 BSPT connection(s).

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/ME6M-18R-SS>

Technical Specifications

| | |
|------------------------------|-----------------------------------|
| Brand | NITRA |
| Item | Pneumatic Push-to-connect Fitting |
| Gender | Male |
| Fitting Type | Elbow |
| Fitting Function | Rotating |
| Body Material | 316 stainless steel |
| Thread Material | 316 stainless steel |
| Thread Sealant | No |
| Connection | 6mm push-to-connect and R1/8 BSPT |
| Operating Pressure | -29.5in Hg to 290 psi |
| Operating Temperature | 32 to 390 deg F |
| For Use With | Flexible pneumatic tubing |

Agency Approvals

| | |
|-----------------------------|--|
| UL Listed File # | None |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | None |
| CSA File # | None |
| RoHS Status | No |
| EU REACH | View EU REACH document |