


ME8M-14R-SS Cut Sheet

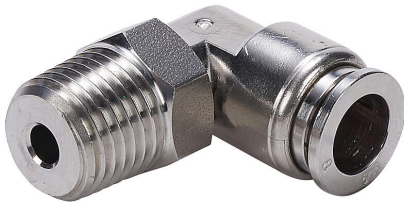

NITRA pneumatic push-to-connect fitting, male, elbow, rotating, 316 stainless steel body, 316 stainless steel threads, 5/16in (8mm) tube to R1/4 BSPT connection(s).

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/ME8M-14R-SS>

Technical Specifications

Brand	NITRA
Item	Pneumatic Push-to-connect Fitting
Gender	Male
Fitting Type	Elbow
Fitting Function	Rotating
Body Material	316 stainless steel
Thread Material	316 stainless steel
Thread Sealant	No
Connection	5/16in (8mm) push-to-connect and R1/4 BSPT
Operating Pressure	-29.5in Hg to 290 psi
Operating Temperature	32 to 390 deg F
For Use With	Flexible pneumatic tubing

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	View EU REACH document