


MI1503-AC Cut Sheet

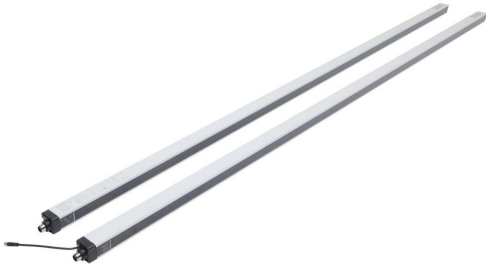

ReeR Micron light grid, sender/receiver pair, measuring, 30mm resolution, 1470mm detection height, 0-10m operating distance, (2) push-pull, (2) 4-20mA analog output, configurable, (1) 5-pin M12 quick-disconnect and (1) 8-pin M12 quick-disconnect.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/MI1503-AC>

Technical Specifications

Brand	ReeR
Series	Micron
Item	Light grid
Light Curtain Type	Sender/receiver pair
Function	Measuring
Beam Resolution	30mm
Detection Height	1470mm
Operating Distance	0-10m
Switching Output	(2) push-pull

Analog Output	(2) 4-20 mA
Configurable	Yes
IP Rating	IP65 IP67
Connection	(1) 5-pin M12 quick-disconnect and (1) 8-pin M12 quick-disconnect
IO-Link Compatible	No
Includes	Mounting hardware
Additional Information	Purchase cable separately

Agency Approvals

UL Listed File #	E469760
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/MI1503-AC.pdf>
See store item page for other formats.