


N532BLU100 Cut Sheet

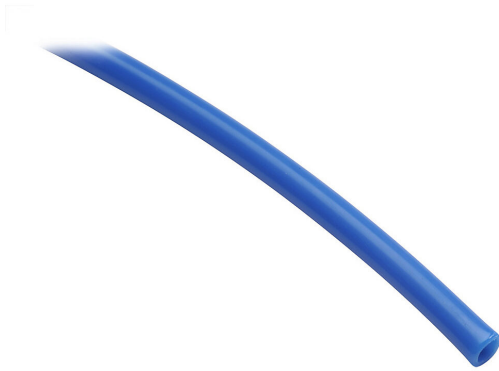

NITRA pneumatic tubing, nylon 12, blue, 5/32in (4mm) outside diameter, 0.106in inside diameter, 100ft package.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/N532BLU100>

Technical Specifications

Brand	NITRA
Item	Tubing
Working Fluid	Air or inert gas
Material	Nylon 12
Color	Blue
Outside Diameter	5/32in (4mm)
Inside Diameter	0.106in
UV stabilized	No
Working Length	100ft package
Operating Pressure	350 psi
Operating Temperature	-60 to +200 deg F

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	View EU REACH document