


# N532YEL500 Cut Sheet

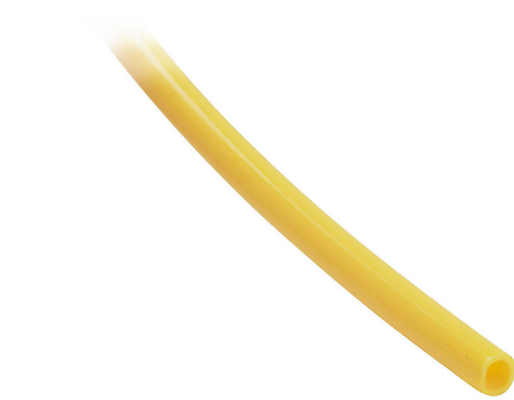

NITRA pneumatic tubing, nylon 12, yellow, 5/32in (4mm) outside diameter, 0.106in inside diameter, 500ft reel.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/N532YEL500>

---

## Technical Specifications

<b>Brand</b>	NITRA
<b>Item</b>	Tubing
<b>Working Fluid</b>	Air or inert gas
<b>Material</b>	Nylon 12
<b>Color</b>	Yellow
<b>Outside Diameter</b>	5/32in (4mm)
<b>Inside Diameter</b>	0.106in
<b>UV stabilized</b>	No
<b>Working Length</b>	500ft reel
<b>Operating Pressure</b>	350 psi
<b>Operating Temperature</b>	-60 to +200 deg F

---

## Agency Approvals

<b>UL Listed File #</b>	None
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	None
<b>CSA File #</b>	None
<b>RoHS Status</b>	No
<b>EU REACH</b>	<a href="#">View EU REACH document</a>