


NC-423-5 Cut Sheet

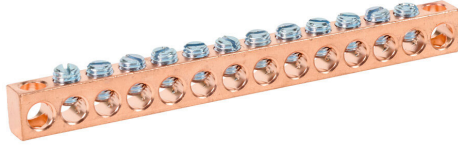

Penn-Union neutral bar, copper, 14 openings, 12 circuits, mounting hole position 1 and 14, copper. Package of 5.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/NC-423-5>

Technical Specifications

Brand	Penn-Union
Item	Neutral bar
Material	Copper
Number Of Openings	14
Number Of Circuits	12
Mounting Hole Position	1 and 14
Conductor Size	14-4 AWG stranded copper and 14-8 AWG solid copper

Conductor Material	Copper
Tightening Torque	14-8 AWG 20 in-lb copper and 6-4 AWG 31 in-lb copper
Application	Neutral and grounding
Quantity per Pack	5

Agency Approvals

UL Listed File #	E12822, E73393
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/NC-423-5.pdf>
See store item page for other formats.