


NC-425-1 Cut Sheet

Penn-Union neutral bar, copper, 15 openings, 13 circuits, mounting hole position 6 and 11, copper.

For complete product information, please see this item on our store at the following link:

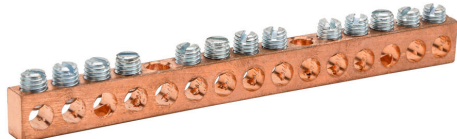

<https://www.automationdirect.com/pn/NC-425-1>

Technical Specifications

| | |
|-------------------------------|---|
| Brand | Penn-Union |
| Item | Neutral bar |
| Material | Copper |
| Number Of Openings | 15 |
| Number Of Circuits | 13 |
| Mounting Hole Position | 6 and 11 |
| Conductor Size | 14-4 AWG stranded copper and 14-8 AWG solid copper |
| Conductor Material | Copper |
| Tightening Torque | 14-8 AWG 20 in-lb copper and 6-4 AWG 31 in-lb copper |
| Application | Neutral and grounding |

Agency Approvals

| | |
|-----------------------------|--|
| UL Listed File # | E73393 |
| UL Recognized File # | E12822 |
| UL Hazardous File # | None |
| CSA File # | None |
| RoHS Status | Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below) |
| EU REACH | View EU REACH document |
| Other | RoHS Statement |

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/NC-425-1.pdf>
See store item page for other formats.