


OA5612-50-24 Cut Sheet

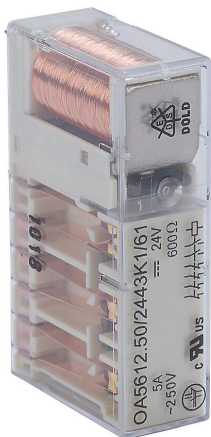

Dold force guided relay, socket mount, encapsulated, 24 VDC coil voltage, 6PST, (2) N.O., (4) N.C., 5A contact rating, 14-pin. Requires HL3096N-102-24 mounting socket.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/OA5612-50-24>

Technical Specifications

| | |
|---------------------|--------------------------------|
| Brand | Dold |
| Item | Relay |
| Relay Type | Force guided |
| Mounting | Socket |
| Relay Housing Type | Encapsulated |
| Coil Voltage | 24 VDC |
| Relay Configuration | 6PST |
| Output Type | (2) N.O., (4) N.C. |
| Contact Rating | 5A |
| Connector Type | 14-pin |
| Requires | HL3096N-102-24 mounting socket |

Agency Approvals

| | |
|----------------------|--|
| UL Listed File # | None |
| UL Recognized File # | E146415 |
| UL Hazardous File # | None |
| CSA File # | None |
| RoHS Status | No |
| EU REACH | View EU REACH document |

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/OA5612-50-24.pdf>
See store item page for other formats.