


# P1-04DAL-2 Cut Sheet

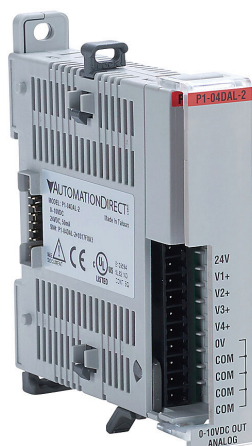

Productivity1000 analog output module, 4-channel, voltage, 12-bit, output voltage signal range(s) of 0-10 VDC, external 24 VDC required.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/P1-04DAL-2>

## Technical Specifications

<b>Brand</b>	Productivity1000
<b>Item</b>	Output module
<b>I/O Module Type</b>	Analog
<b>Number Of Output Channels</b>	4
<b>Output Signal Type</b>	Voltage
<b>Analog Output Type</b>	Sourcing
<b>Isolated Channels</b>	No
<b>Number of Non-Isolated Output Commons</b>	1
<b>Output Resolution</b>	12-bit
<b>Output Voltage Signal Range</b>	0-10 VDC
<b>External Power Requirement</b>	24 VDC
<b>Requires</b>	P1-10RTB or P1-10RTB-1 removable terminal block or ZIPLink pre-wired cables
<b>Programming Software</b>	Productivity Suite programming software v3.0 or later

## Agency Approvals

<b>UL Listed File #</b>	E139594
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	None
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>